


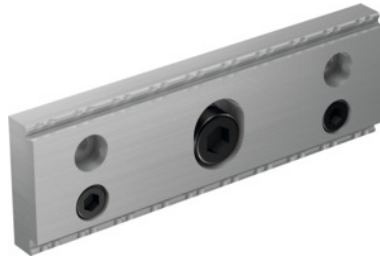

Front jaw, for jaw width: 125 mm



Order data

Order number	362392 125
GTIN	4045197973108
Item class	31S

Description

Version:

High precision when clamping. The additional jaws greatly extend the application range of your vice. Optimised tooth profile for high retention forces.

Reversible jaw with 2 clamping steps. One clamping step of 3 mm height and one clamping step of 5 mm height.

Jaw width b: 12 mm

Jaw height h: 40 mm

suitable for colour code: Titan 2

suitable for colour code: LC

suitable for colour code: LC-Garant

suitable for colour code: HD Allmatic

Technical description

Jaw width b	12 mm
Jaw height h	40 mm
suitable for colour code	Titan 2
suitable for colour code	LC
suitable for colour code	LC-Garant
suitable for colour code	HD Allmatic

suitable for colour code	HD Horex
suitable for colour code	Basic
suitable for colour code	LCV125G
suitable for colour code	TC
suitable for colour code	NC8
suitable for colour code	HiPo
suitable for colour code	NC8
for jaw width	125 mm